

**E 93300**




**Klemmhebel mit Innengewinde, Thermoplast**

*Handle with internal thread, thermoplastic*

» Spannstellung verstellbar

» Adjustable clamping position

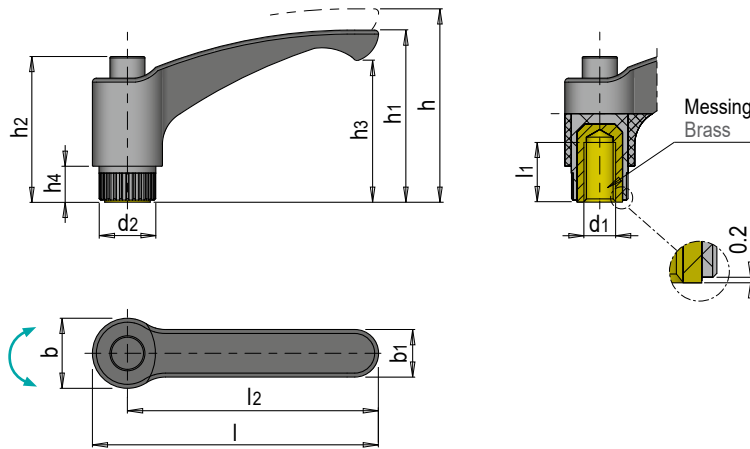

Mat.: Polyamid PA, glasfaserverstärkt  
polyamide PA, glass fibre reinforced

b	l	h	l1	b1	h1	d2	h2	l2	h3	h4	d1	Nr. / No.
15.5	52	36	10	11	32.5	12	29.5	44	25	6	<b>M 6</b>	E 93300/ 6
19	73.5	47	13	13.5	43	15	37.5	63	34.5	8	<b>M 8</b>	E 93300/ 8
24.5	90.5	58	18	16	54	19	47	78	44	12	<b>M10</b>	E 93300/10
26.5	109	69	20	18	64.5	21.5	54.5	95	53	13	<b>M12</b>	E 93300/12