


E 93350



Verstellbarer Spannhebel mit Innengewinde

Adjustable handle with internal thread

- » Schräger Hebel
- » Kugelkopf DIN 319
- » Diagonal lever
- » Ball head according to DIN 319

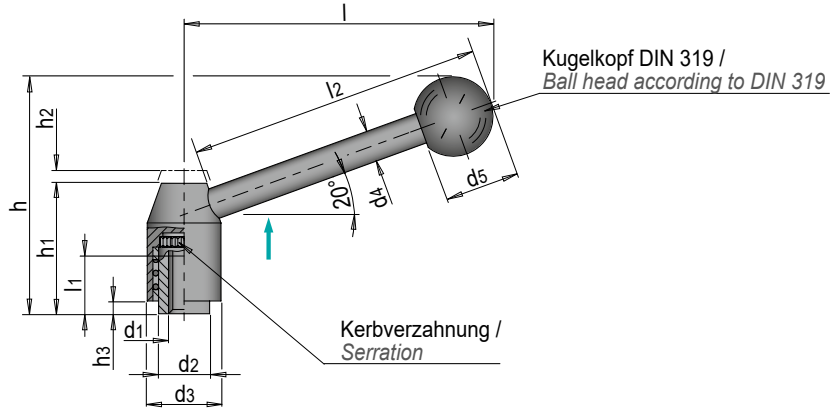

Mat.: Stahl, brüniert / steel, black oxidized 5.8

h	l	h1	l1 min.	d2	h2	l2	h3	d4	d5	d3	d1	Nr. / No.
59	75	33.5	11	13.5	4	70	1	8	20	21	M 8	E 93350/21/ 8
75	101	40	14	16	4.5	96	2.5	10	25	24	M10	E 93350/24/10
89	116	48.5	17	19		110	4.5	12	30	28	M12	E 93350/28/12