


PRODUKTBESCHREIBUNG

» Nach DIN 6316

MATERIAL

» Vergütungsstahl, lackiert

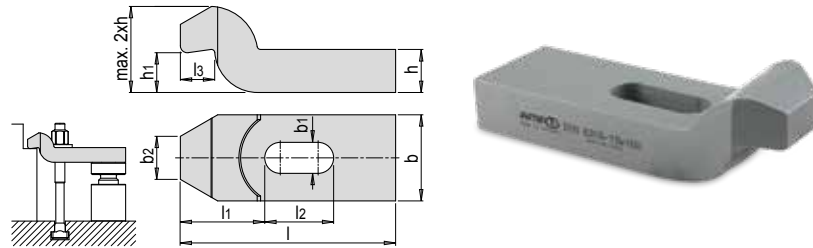

b	b2	h	h1	l1	l2	l3	M ¹⁾	b1	l	Nr.	EUR
20	10	10	9	22	20	8	M6	6,6	60	HWS 118/ 6,6/ 60	<>
25	12	12	11	27,5	25	9	M8	9	80	HWS 118/ 9 / 80	<>
30	15	15	14	36	32	12	M10	11	100	HWS 118/11 /100	<>
40	20	20	18	44	40	16	M12, M14	14	125	HWS 118/14 /125	<>
50	25	25	23	51,5	40	20	M16, M18	18	125	HWS 118/18 /125	<>
50	25	25	23	51,5	50	20	M16, M18	18	160	HWS 118/18 /160	<>
60	30	30	27	59	55	24	M20, M22	22	160	HWS 118/22 /160	<>
60	30	30	27	59	70	24	M20, M22	22	200	HWS 118/22 /200	<>

1) M: Passend für Spannschraube